


Base Plates • overall dimensions same as pallets DIN 55 201

1100.800

Product Description

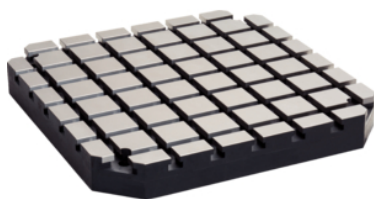

Material


- Steel, case-hardened, ground

More information

Notes

Special types on request.


Drawing

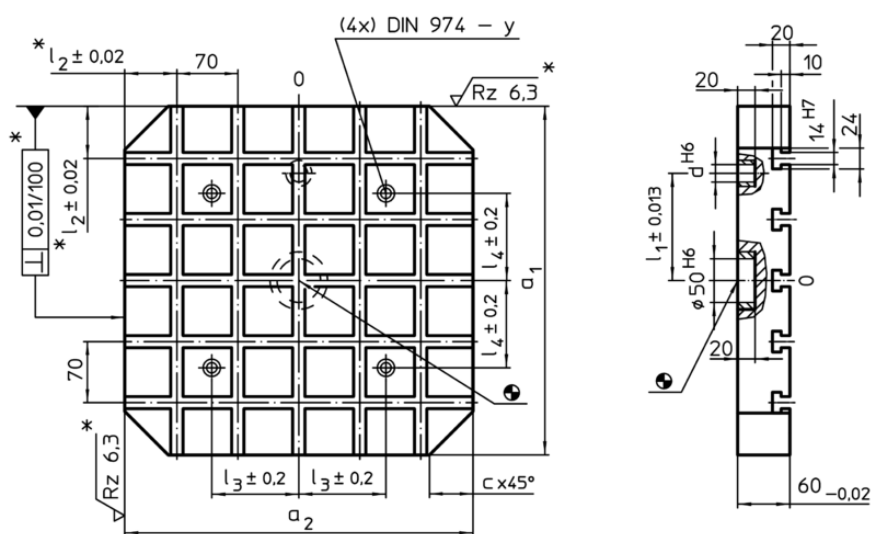

Slot spacing 70 ± 0.01 .

* These tolerances are valid only for the exterior stop types.

Order information

System	Dimensions							For screws	y	Number of T-slots	 [kg]	Art. No.
	$a_1 \times a_2$	c	d	l_1	l_2	l_3	l_4					
V70	500 x 500	60	20	200	40	200	200	M12	12	7 x 7	84	1100.800

Application example

