


Base Plates • overall dimensions same as pallets DIN 55 201

1100.900

Product Description

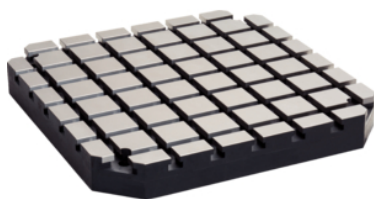

Material


- Steel, case-hardened, ground

More information

Notes

Special types on request.


Drawing

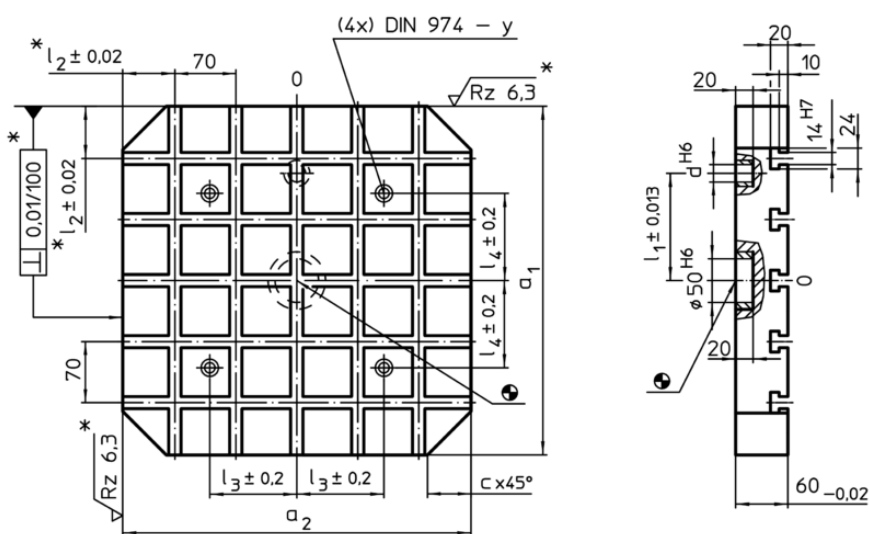

Slot spacing 70 ± 0.01 .

* These tolerances are valid only for the exterior stop types.

Order information

System	Dimensions							For screws	y	Number of T-slots	 [kg]	Art. No.
	$a_1 \times a_2$	c	d	l_1	l_2	l_3	l_4					
V70	630 x 630	70	25	200	35	200	200	M16	16	9 x 9	129	1100.900

Application example

