


Base Plates • overall dimensions same as pallets DIN 55 201

1103.300

Product Description

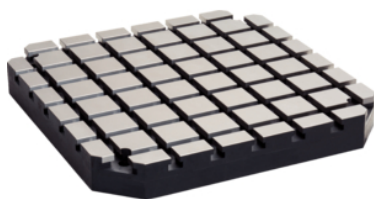

Material


- Steel, case-hardened, ground

More information

Notes

Special types on request.

Drawing

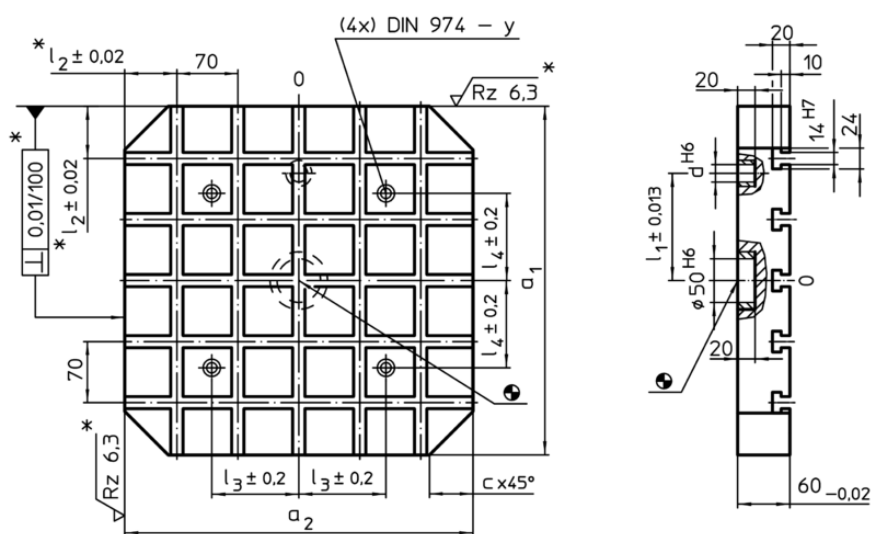

Slot spacing 70 ± 0.01 .

* These tolerances are valid only for the exterior stop types.

Order information

System	Dimensions							For screws	y	Number of T-slots	[kg]	Art. No.
	$a_1 \times a_2$	c	d	l_1	l_2	l_3	l_4					
V70	400 x 500	50	20	150	60/40	200	100	M12	12	5 x 7	69	1103.300

Application example

