


Base Plates • overall dimensions same as pallets DIN 55 201  
1103.500

Product Description

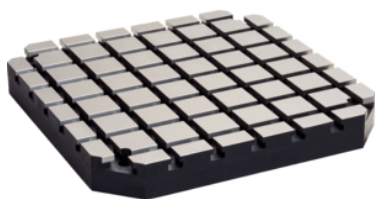

Material


- Steel, case-hardened, ground

More information

Notes

Special types on request.


Drawing

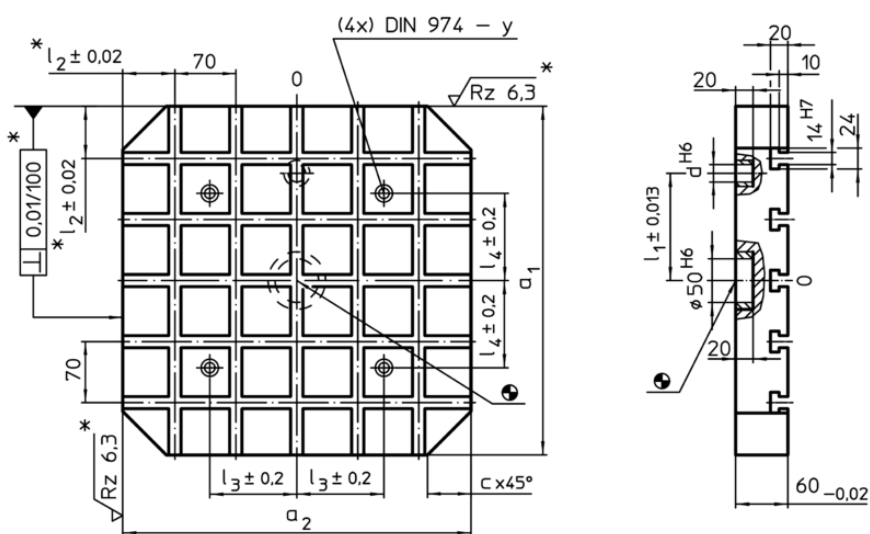

Slot spacing  $70 \pm 0.01$ .

\* These tolerances are valid only for the exterior stop types.

Order information

System	Dimensions							For screws	y	Number of T-slots	 [kg]	Art. No.
	$a_1 \times a_2$	c	d	$l_1$	$l_2$	$l_3$	$l_4$					
V70	500 x 630	60	20	200	40/35	200	200	M12	12	7 x 9	107	1103.500

Application example

