

## Base Plates• V70eco, overall dimensions same as pallets DIN 55201

1200.700

### Product Description



V70eco base plates are a further development of the established V70 product line, optimized in quality and price.

They are fully compatible with the existing V70 T-slot System.

- Centers to H6 tolerance and slots to H8 tolerance.
- Alignment of the base plate on the machine table by means of centers and/or centering slot.
- Fastening holes on a 100 mm pitch.
- High tensile tool steel.

Available options (delivery time of 10 working days):

- Additional fixing holes on a 63 mm pitch.
- Additional fixing holes on a 125 mm pitch.
- Exterior stop.
- With connecting rings for Halder Zero-Point Clamping System.

### Material


- Tool steel, high-strength

### More information

### Notes


Special types on request.

### Drawing

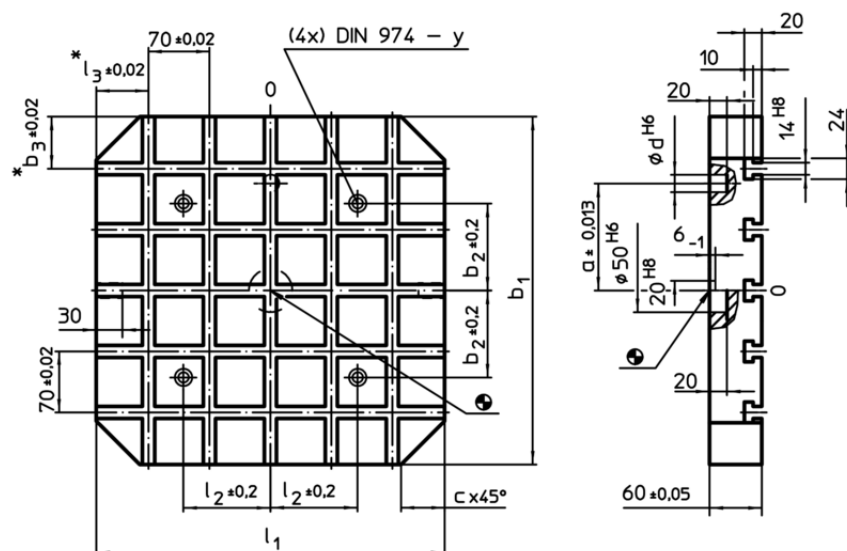

\* These tolerances are valid only for the exterior stop types.

### Order information

System	Dimensions									Number of connecting rings Zero-Point Clamping System (optional)	Number of T-slots		Art. No.
	l <sub>1</sub>	b <sub>1</sub>	a	b <sub>2</sub>	b <sub>3</sub>	c	d	l <sub>2</sub>	y				
				±0,2	±0,02			±0,2					
				[mm]									
V70	400	400	150	100	60	50	20	100	12	4	5 x 5	61	1200.700