


## Base Plates• V70eco, overall dimensions same as pallets DIN 55201

1200.900

### Product Description

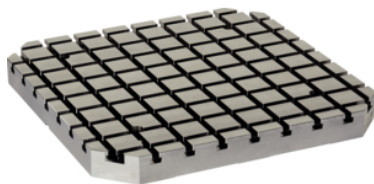

V70eco base plates are a further development of the established V70 product line, optimized in quality and price.

They are fully compatible with the existing V70 T-slot System.

- Centers to H6 tolerance and slots to H8 tolerance.
- Alignment of the base plate on the machine table by means of centers and/or centering slot.
- Fastening holes on a 100 mm pitch.
- High tensile tool steel.

Available options (delivery time of 10 working days):

- Additional fixing holes on a 63 mm pitch.
- Additional fixing holes on a 125 mm pitch.
- Exterior stop.
- With connecting rings for Halder Zero-Point Clamping System.

### Material


- Tool steel, high-strength

### More information

### Notes

Special types on request.

### Drawing

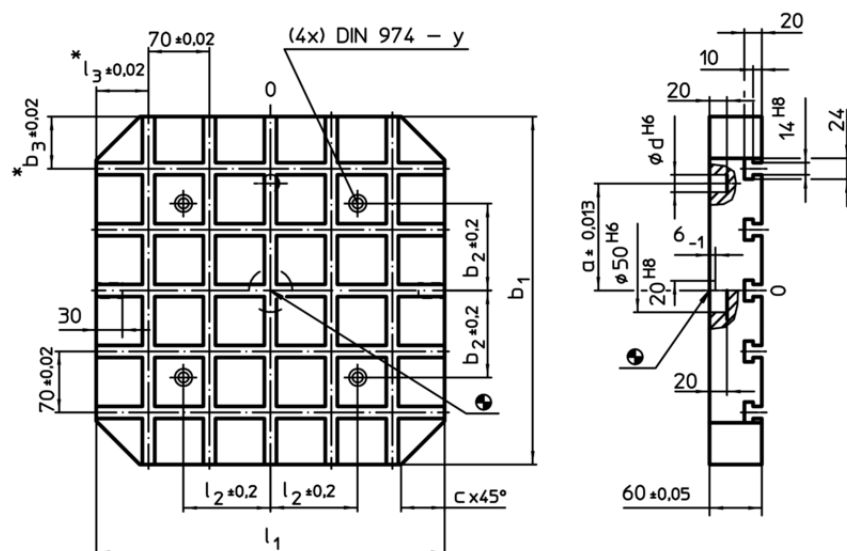

\* These tolerances are valid only for the exterior stop types.

### Order information

System	Dimensions									Number of connecting rings Zero-Point Clamping System (optional)	Number of T-slots	[kg]	Art. No.
	$l_1$	$b_1$	$a$	$b_2$ $\pm 0,2$	$b_3$ $\pm 0,2$	$c$	$d$	$l_2$ $\pm 0,2$	$y$				
				[mm]									
V70	630	630	200	200	35	70	25	200	16	4	9 x 9	152	1200.900