


Base Jaws• hard
1701.130

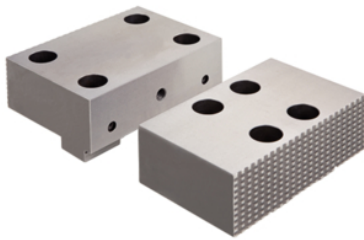


Product Description

- One side smooth and ground, one side serrated
- Additional threads for parallels and for mounting the interchangeable jaws (Art. No. 1701.250-1701.280) on the smooth side
- Mountings for click system (Art. No. 1701.190-1701.200) on both sides of the jaw


Material

- Steel, hardened

Drawing

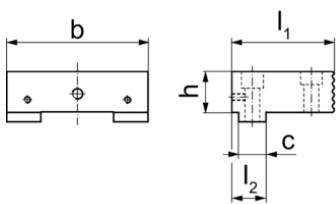

picture 1

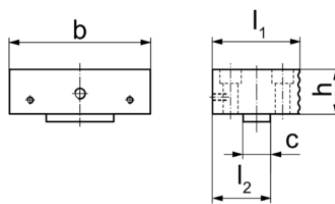


picture 2

Order information

Jaw width [mm]	Dimensions					[g]	Art. No.
	b	l ₁	l ₂ [mm]	h	c		
Jaw, movable – picture 2							
125	124,4	76	50	39,5	24	3000	1701.130

Application example

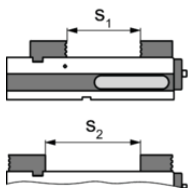

	MS 125-S	MS 125-M	MS 125-L
Clamping width s ₁	0 - 58	0 - 173	0 - 308
Clamping width s ₂	0 - 111	50 - 225	4 - 361